

# 4 in. Octagonal Extension Rings and Covers

# IBERVILLE®



OBEX-CRT



55151K-CRT




54C1-CRT



54C6-CRT



54C65-CRT

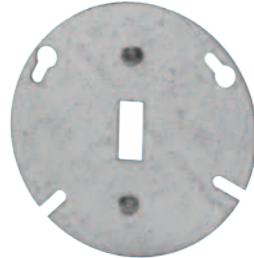

54C94-CRT



CPC4WH



54COV1-CRT



Cat. No.	Cubic Capacity	Ground Screws	Conduit Knockouts	Description
<b>1/2 IN. DEEP - EXTENSION RING</b>				
OBEX-CRT	5.0			Extension ring for octagonal boxes; non-adjustable depth of 1/2. Complete with mounting screws.
<b>1-1/2 IN. DEEP - EXTENSION RING</b>				
55151K-CRT	15.0	1	2 x K + 2 x 1/2 in.	Extension ring for octagonal boxes; non-adjustable depth of 1-1/2.
<b>2-1/8 IN. DEEP - EXTENSION RING</b>				
CI55171-K	21.0	1	2 x K + 2 x 1/2 in.	Extension ring for octagonal boxes; non-adjustable depth of 2-1/8.
<b>4 IN. ROUND COVERS</b>				
54C1-CRT				Flat blank cover.
54C1-EP				Flat blank cover. Carton of 50 units.
54C6-CRT			1 x 1/2 in.	Flat cover.
CI54-C-64				Flat cover for 15 A, 1-13/32 in. diameter single receptacle. Complete with device mounting screws.
54C65-CRT				Flat cover for duplex receptacle. Complete with device mounting screw.
54C94-CRT				Flat cover for toggle switch. Complete with device mounting screws.
CPC4WH *				White finish PVC cover
<b>5 IN. ROUND COVERS</b>				
BC-54-COV			1 x 1/2 in.	Flat cover. Mounting screws included.
54COV-1-CRT				Flat blank cover. Mounting screws included.

\*cULus