



BC1018-LHTQ



1304LHTQ-CRT



BC2004-LHTQ



2304LHTQ-CRT




BC3104-LHTQ



2304LHTQ2-CRT



BC2304-LHTQ-3

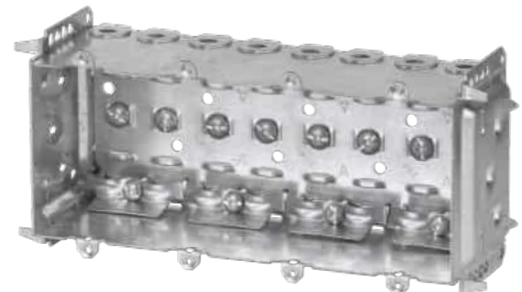

BC2304-LHTQ-4



Cat. No.	Dimensions H x W x D (in.)	Cubic Capacity	Gangable	One Screw mounting	Position Tabs	Prov. for external nailing	Pryouts Ends
BC1018-LHTQ	3 x 2 x 3	18.0	Yes	Yes	Yes	Yes	4
1304LHTQ-CRT	3 x 2 x 2-1/2	14.5					
BC1304-LHATQ	3 x 2 x 2-1/2	14.5					
BC2004-LHTQ	3-3/4 x 2-3/16 x 2-3/4	20.5	No	No	Yes	Yes	8
2304LHTQ-CRT	3 x 2 x 2-1/2	14.5					
2304LHTQ2-CRT	3 x 3-3/4 x 2-1/2	27.0					
BC2304-LHTQ-3	3 x 5-1/2 x 2-1/2	39.5					
BC2304-LHTQ-4	3 x 7-3/8 x 2-1/2	52.0					
BC3104-LHTQ	3 x 2 x 2-1/2	16.0	Yes	Yes	Yes	Yes	4

- CSA approved one (1) screw mounting (one + 2304LHTQ2-CRT)
- Retractable positioning tabs for double 1/2" drywall installations
- Three embossed slots for screw mounting
- Sides are flat for maximum stability
- Holding prongs