


Concealed Service Floor Boxes

Steel City®

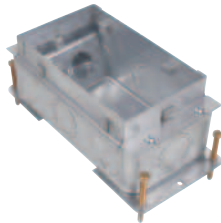

663-SC



664-SC



664 CI



664 S




664-CST



664 S RP



664 RP

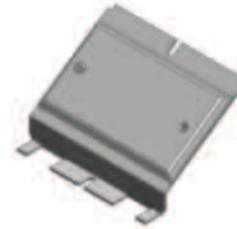

664 BP




664 GP




Cat. No.	Description	Features	Size (in.)		
			Height	Width	Length
663-SC	Two gang box - steel	—	3-5/8	4-11/16	8-13/16
P 60 3B	Cover plate	Polished brass c/w 1 P 60 Q	—	—	—
P 60 CP	Carpet plate	Polished brass			
P 60 CP AL		Aluminum			
P 60 Q	Duplex receptacle plate - steel	—			
P 60 QB	Blank Plate - steel	—			
P 62 CP AS	Cover and carpet flange	Charcoal, c/w one P 60 Q			
P 62 CP BRN		Brown, c/w one P 60 Q			
P 62 CP G		Gold, c/w one P 60 Q			
P 62 TAR	Flange and adjusting ring	—			
P-62-TAR-AL	Flange and adjusting ring - aluminum	—			
664-SC	Two gang box - cast iron	c/w one 664 RP	3-3/4	4-11/16	10-1/4
664 S	Shallow two gang recessed floor box	c/w one 664 RP	2-7/8	4-11/16	10-1/4
664 CI	Two gang recessed floor box	c/w one 664 RP	3-3/4	5-3/32	9-15/16
664 BP	Blank device plate	Use with 664-SC and 664 CI	—	—	—
664-CST-SW-BGE	Carpet flange and cover	Beige - scrubwater tight			
664-CST-SW-BLK		Black - scrubwater tight			
664-CST-SW-BRN		Brown - scrubwater tight			
664-CST-SW-GRY		Grey - scrubwater tight			
664 GP	Panel for one GFCI receptacle	—			
664 RP	Panel for one duplex receptacle	Use with 664-SC and 664 CI			
664 S BP	Blank plate	Use with 664 S			
664 S RP	Panel for 1 duplex receptacle				
664 S WT*	Wire tunnel				
664 WT		Use with 664-SC and 664 CI			

* UL Listed

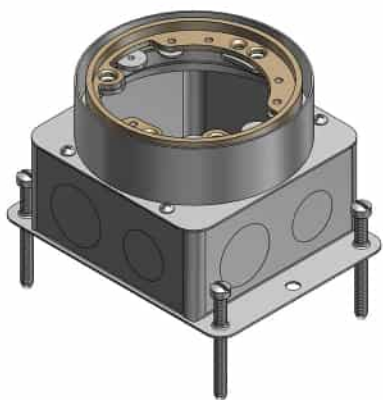

68 D

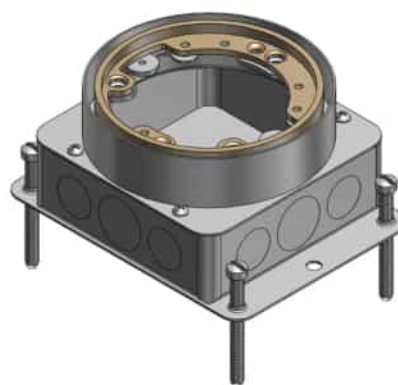

68 S



Cat. No.	Description	Features	Conduit knockouts (in.)		Size (in.)		
			Sides	Bottom	Height	Width	Length
68 D	Floor box	Steel	(4) 3/4	(2) 1/2	3-5/8	4-1/4	4-11/16
68 S		Steel c/w aluminum trim ring	(4) 1	(2) 3/4	2-3/4		
68 S AL							