


Set-Screw Vibration Proof / Visible Connection

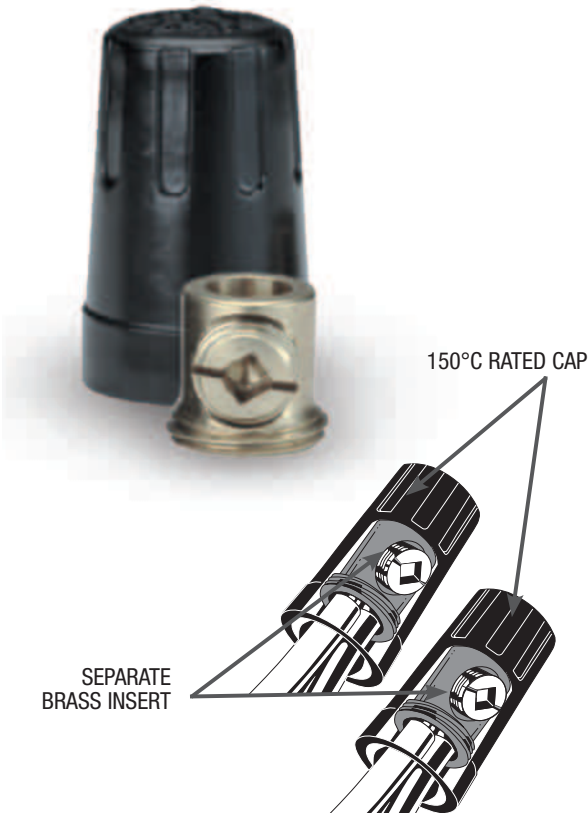

External Cap

- Made of rugged material and 150°C rated.
- Insulator cap locks securely in place to safeguard against accidental loosening in high vibration applications.

Brass Insert

- Choice of Slotted or Robertson screw-driver installation. When tightened into the insert, provides a solid pressure type connection on all approved wire combinations.
- No need to “re-strip” wires when rewiring. Simply loosen screw to remove non-twisted wires.
- Brass sleeve + set-screw help resist corrosion.
- Approved for circuits up to 600 V, and lighting fixtures and signs up to 1000 V.
- For copper wire only.
- Convenient packaging - sized right and job-site ready!

For packaging options, see page D19



Model	Description	18	16	14	12	10	8
1SHB, 1SHD, 1SHP, 1C-CDN	Cap and insert combination screw and brass barrel.	Min.: 2 #18 Max.: 1 #18 + 3 #14					
2SHB, 2SHD, 2SHP, 2C-CDN	Cap and insert combination screw and brass barrel.		Min.: 2 #14 Max.: 1 #12 + 2 #10				
2SHi	Insert screw and brass barrel only.		Min.: 2 #14 Max.: 1 #12 + 2 #10				

Nbr of Cond.	AWG	Nbr of Cond.	AWG
1SH			
1	18	1	14
1	18	2	14
1	18	3	14
2	18	—	—
2	18	1	14
2	18	2	14
3	18	—	—
3	18	1	14
4	18	—	—
5	18	—	—
6	18	—	—
7	18	—	—
8	18	—	—
1	16	1	14
2	16	—	—
2	16	1	14
3	16	—	—

Nbr of Cond.	AWG	Nbr of Cond.	AWG
4	16	—	—
5	16	—	—
2	14	—	—
3	14	—	—
2	12	—	—
2SH			
1	16	2	14
2	16	1	14
2	16	2	14
3	16	1	14
2	10	—	—