

# Lever Wire Connectors

**marrette**




2 Ports



3 Ports



4 Ports

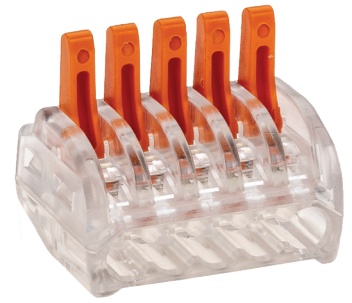

5 Ports

- **Temperature Rating:** 105 °C (221 °F) max.
- **Wire Range:** #28 to #12 solid or stranded CU only
- **Flame Rating:** UL 94 V-2
- **Strip Length:** 10 mm (0.39 in.)

### Features:

- Lever for easy insertion and release of wires
- Heavy duty compact design
- Reusable
- Continuity test slot

### Application Approval

cULus listed as a wire connector for 600 V max. building wire / 1,000 V max. in signs or fixtures.



Cat. No.	Number of ports	Colour	Wire Range	Packaging
CLTC2B50	2	Orange	#28 to #12 solid or stranded CU only	Window box of 50 units
CLTC2M10				Clamshell of 10 units
CLTC2P				Propak of 100 units
CLTC3B25	3			Window box of 25 units
CLTC3M5				Clamshell of 5 units
CLTC3P				Propak of 100 units
CLTC4B25	4			Window box of 25 units
CLTC4M5				Clamshell of 5 units
CLTC4P				Propak of 50 units
CLTC5B25	5			Window box of 25 units
CLTC5M4				Clamshell of 4 units
CLTC5P				Propak of 50 units