


2 Ports

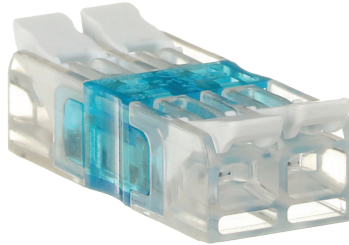

4 Ports



6 Ports

- **Temperature Rating:** 90 °C (194 °F) max.
- **Wire Range:** #24 to #12 solid / #22 to #14 stranded CU only
- **Flame Rating:** UL 94 V-2
- **Strip Length:** 13-14 mm (0.51-0.55 in.)

Features:

- Allow easy in-line splicing connections
- Lever for easy insertion and release of wires
- Compact design
- Reusable
- Continuity test slot

Application Approval

cULus listed as a wire connector for 600 V max. building wire / 1,000 V max. in signs or fixtures.



Cat. No.	Number of ports	Colour	Wire Range	Packaging
LTLC2M8	2	Blue	#24 to #12 solid / #22 to #14 stranded CU only	Clamshell of 8 units
LTLC2B40				Propak of 400 units
LTLC2P				Propak of 100 units
LTLC4M5	4			Clamshell of 5 units
LTLC4B25				Propak of 25 units
LTLC4P				Propak of 100 units
LTLC6M4	6			Clamshell of 4 units
LTLC6B15				Propak of 15 units
LTLC6P				Propak of 50 units