


Nonmetallic Sheathed Cable Accessories

IBERVILLE®

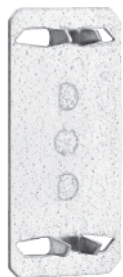

CI66-PPH



66



CI66-FPP



66-SS-EP



BC66-T



CI66-XL



CI66-XL-2



Cat. No.	Alloy	Hole Size (in.)	Dimensions (in.)		Suggested Applications NMD90 (LOOMEX)	Packaging
			Height	Width		
PROTECTOR PLATES						
66-EP	Steel	1-3/8 x 3	3	1-3/8	For wood stud	Box of 50 units
66M4						Clamshell of 4 units
66P25						Box of 25 units
66-V2-RP						Bag of 5 units
66RPS-80						Rack Pack System of 80 units
CI66-FPP		2-3/8 x 3-1/2	3-1/2	2-3/8	For forenze	
66-SS-EP		3 x 1-1/4	3	1-3/8	For steel stud	Box of 25 units
CI66-PPH	Stainless Steel		1-1/4	4-7/16	Exterior walls in front of wood stud	
BC66-T		3/4 – 7/8	3/4	4-1/4	For wood stud	
CI66-XL			3-11/16			
CI66-XL-2						8-1/2

C.E.C. 2012 rule 12-516 (1) Where the cable is run through studs, joints, or similar members, the outer surface of the cable shall be kept distant at least 32 mm (1-1/4 in.) from the edges of the members or the cable shall be effectively protected from mechanical injury.