



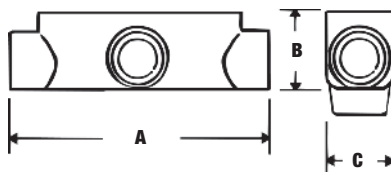


CITA-1/2 / CITA-4



CITBA-1/2 / CITBA-2

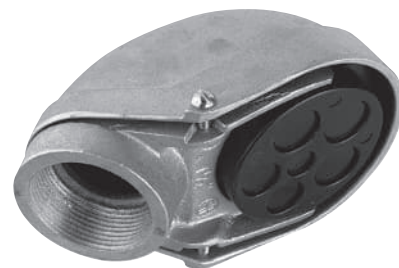

CIEFA-1/2 / CIEFA-4

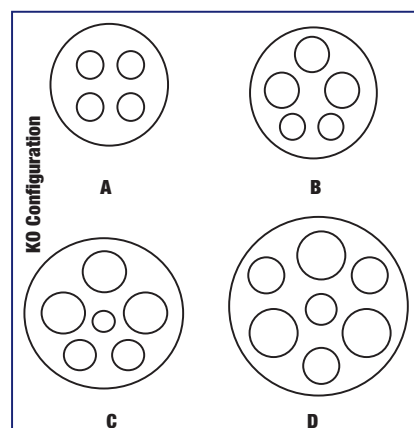

Cat. No.	Alloy	Trade Size (in.)	Dimensions (in.)			Applications
			A	B	C	
TYPE T CONDUIT FITTINGS						
CITA-1/2	Al	1/2	4-7/8	1-3/8	2-1/16	Use with EMT or Rigid
CITA-3/4		3/4	5-9/16	1-3/4	2-1/8	
CITA-1		1	6-1/2	2	2-1/2	
CITA-1 1/4		1-1/4	8-11/16	2-5/8	3-1/2	
CITA-1 1/2		1-1/2		3	3-9/16	
CITA-2		2	10-7/8	3-1/4	4-3/16	Use with Rigid only
CITA-2 1/2		2-1/2	12-5/8	6-3/8	5-3/4	
CITA-4		4	14-7/8	7-1/8	6-3/4	
TYPE TB CONDUIT FITTINGS						
CITBA-1/2	Al	1/2	4-3/8	1-3/8	1-3/8	Use with Rigid only
CITBA-3/4		3/4	5-1/8	2-1/8	1-9/16	
CITBA-1		1	6	2-1/2	1-13/16	
CITBA-1 1/4		1-1/4	8-1/8	3-1/2	2-1/2	
CITBA-1 1/2		1-1/2				
CITBA-2		2	10-1/4	4-5/16	3-1/8	

*Gaskets and covers are included with all rigid conduit fittings.

Cat. No.	Alloy	Trade Size (in.)	Small (in.)	Large (in.)	Center (in.)	Applications	KO conf.
SERVICE ENTRANCE HEADS							
CIEFA-1/2	Al	1/2	0.312	—	—	Use only with Rigid Conduit	A
CIEFA-3/4		3/4	0.375	0.400	—		B
CIEFA-1		1	0.438	0.500	—		
CIEFA-1 1/4		1-1/4		0.625	—		C
CIEFA-1 1/2		1-1/2	0.610	0.750	0.400		
CIEFA-2		2	0.750	1.000	0.525		D
CIEFA-2 1/2		2-1/2	0.875	1.300	1.000		
CIEFA-3		3	1.125	1.750	1.125		
CIEFA-3 1/2		3-1/2					
CIEFA-4		4					