

EMT Conduit Fittings and Entrance Caps


IBERVILLE®



CILRL-1/2 / CILRL-2




CITA-1/2 / CITA-2

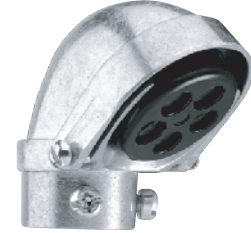

CIEFSA-1/2 / CIEFSA-4



KO Configuration

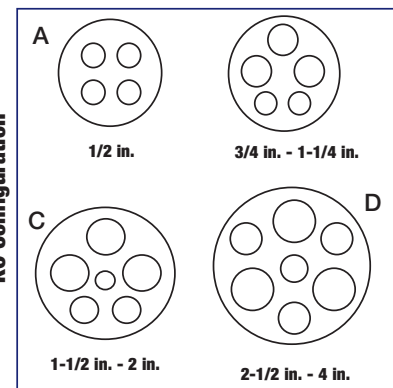

Cat. No.	Alloy	Trade Size (in.)	Dimensions (in.)			Applications
			A	B	C	
EMT CONDUIT FITTINGS - "LRL" TYPE						
CILRL-1/2	Aluminum	1/2	4.44	1.69	2.13	Use with EMT or Rigid
CILRL-3/4		3/4	3.18	1.88	2.25	
CILRL-1		1	6.00	2.19	2.50	
CILRL-1 1/4		1-1/4	7.94	2.75	3.50	
CILRL-1 1/2		1-1/2	7.94	3.25	3.50	
CILRL-2		2	10.19	3.69	4.13	
EMT CONDUIT FITTINGS - "T" TYPE						
CITA-1/2	Aluminum	1/2	4.88	1.38	2.1	Use with EMT or Rigid
CITA-3/4		3/4	5.56	1.75	2.13	
CITA-1		1	6.50	2.00	2.50	
CITA-1 1/4		1-1/4	8.69	2.63	3.50	
CITA-1 1/2		1-1/2	8.69	3.00	3.56	
CITA-2		2	10.88	3.25	4.56	

Cat. No.	Alloy	Trade Size (in.)	Knockouts (in.)			Applications	Knockout Configuration
			Small	Large	Center		
SERVICE ENTRANCE HEADS							
CIEFSA-1/2	Aluminum	1/2	0.312	—	—	Use with EMT only	A
CIEFSA-1 1/2		1-1/2	0.610	0.750	0.400		C
CIEFSA-2 1/2		2-1/2	0.875	1.300	1.000		D
CIEFSA-3		3	1.125	1.750	1.125		D
CIEFSA-3 1/2		3-1/2	1.125	1.750	1.125		D
CIEFSA-4		4	1.125	1.750	1.125		D