


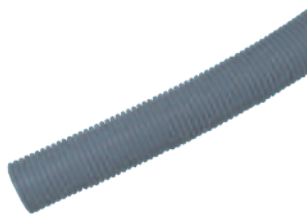

15004-100 / 15011-050



12005C / 12008



VC9995C-RT



Cat. No.	Nominal Size (in.)	Avg. O.D. (in.)	Avg. I.D. (in.)	Length Reel (ft.)	Std. Reel Wt. (lb.)
LIQUIDTIGHT FLEXIBLE NONMETALLIC CONDUITS (COILS)					
15004-100	3/8	0.700	0.489	100	11.70
15005C-025	1/2	0.830	0.627	25	6.50
15005-100	1/2	0.830	0.627	100	13.00
15007-100	3/4	1.040	0.825	100	18.00
15008-100	1	1.302	1.046	100	28.00
15009-100	1-1/4	1.645	1.385	100	37.60
15010-100	1-1/2	1.882	1.580	100	47.80
15011-050	2	2.357	2.025	50	34.10

Standard colour Grey
Also available in reels

- Chemical resistant
- Corrosion-free
- Temperature range: -18 °C to 75 °C (0 °F to 167 °F)



Cat. No.	Nominal Size (in.)	Colour	Nominal I.D. (in.)	Nominal O.D. (in.)	Coil Length (ft.)
ENT NONMETALLIC CONDUITS (COILS)					
12005C-010	1/2	Blue	0.56	0.84	10
12007C-010	3/4		0.76	1.05	10
12008C-010	1		1.00	1.375	10
12008C-025	1		1.00	1.375	25
12008C-100	1		1.00	1.375	100

Cat. No.	Description
VC9995C-RT	All weather ENT blue cement with brush. Size 1/4 pint can.