


Malleable Iron Liquidtight Fittings

IBERVILLE®



CI6103 (-IT) / CI6116 (-IT)
IT: with insulated throat.

- Heavy duty malleable iron
- Zinc electroplated for corrosion resistance
- Tapered threaded hub complete with nitrile “O” ring and steel locknut

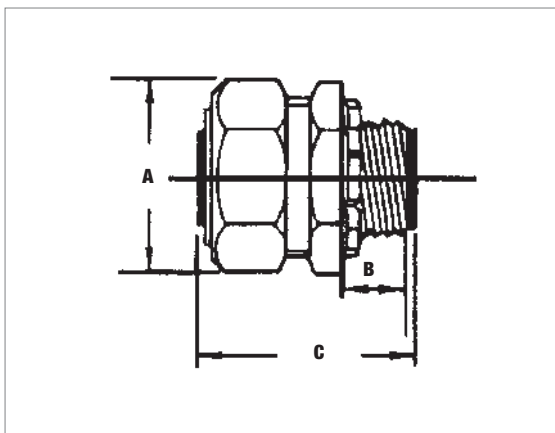

Cat. No.	Alloy	Trade Size (in.)	Knockout Size (in.)	Dimensions (in.)		
				A	B	C
STRAIGHT LIQUIDTIGHT FITTINGS						
CI6103	Malleable Iron	3/8	1/2	1-1/8	1/2	1-1/2
CI6104		1/2		1-1/4		
CI6106		3/4	3/4	1-1/2	9/16	1-3/4
CI6108		1	1	1-3/4	5/8	1-7/8
CI6110		1-1/4	1-1/4	2-1/4	11/16	2-3/16
CI6112		1-1/2	1-1/2	2-9/16	13/16	2-3/8
CI6116		2	2	3-1/16	15/16	2-7/8
STRAIGHT INSULATED LIQUIDTIGHT FITTINGS						
CI6103-IT	Malleable Iron	3/8	1/2	1-1/8	1/2	1-9/16
CI6104-IT		1/2		1-1/4		
CI6106-IT		3/4	3/4	1-1/2	9/16	1-13/16
CI6108-IT		1	1	1-3/4	5/8	1-15/16
CI6110-IT		1-1/4	1-1/4	2-1/4	11/16	2-1/4
CI6112-IT		1-1/2	1-1/2	2-9/16	13/16	2-7/16
CI6116-IT		2	2	3-1/16	15/16	2-5/16