


CI6303 (-IT) / CI6316 (-IT)

IT: with insulated throat.

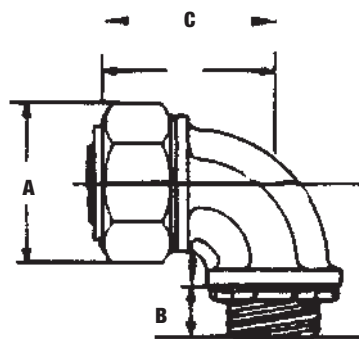

Cat. No.	Alloy	Trade Size (in.)	Knockout Size (in.)	Dimensions (in.)		
				A	B	C
90° LIQUIDTIGHT FITTINGS						
CI6303	Malleable Iron	3/8	1/2	1-1/8	1/2	1-5/8
CI6304		1/2		1-1/4		1-3/4
CI6306		3/4	3/4	1-1/2	9/16	2-1/16
CI6308		1	1	1-3/4	5/8	2-1/4
CI6310		1-1/4	1-1/4	2-1/4	11/16	2-3/4
CI6312		1-1/2	1-1/2	2-9/16	13/16	3-1/8
CI6316		2	2	3-1/16	15/16	3-3/8
90° INSULATED LIQUIDTIGHT FITTINGS						
CI6303-IT	Malleable Iron	3/8	1/2	1-1/8	1/2	1-5/8
CI6304-IT		1/2		1-1/4		1-3/4
CI6306-IT		3/4	3/4	1-1/2	9/16	2-1/16
CI6308-IT		1	1	1-3/4	5/8	2-1/4
CI6310-IT		1-1/4	1-1/4	2-1/4	11/16	2-3/4
CI6312-IT		1-1/2	1-1/2	2-9/16	13/16	3-1/8
CI6316-IT		2	2	3-1/16	15/16	3-3/8