


Zinc Liquidtight Fittings

IBERVILLE®



CI6603 (-IT) / CI6632 (-IT)
IT: with insulated throat.

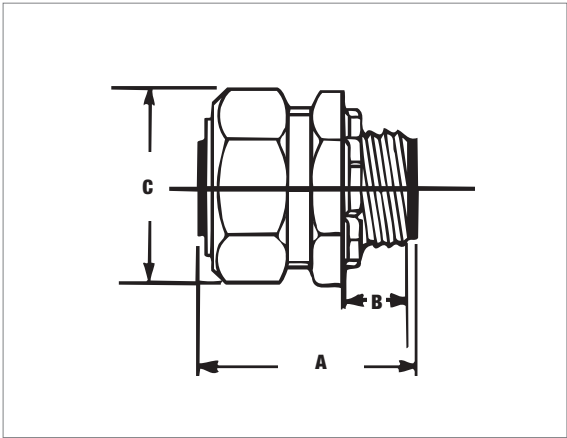

Cat. No.	Alloy	Trade Size (in.)	Knockout Size (in.)	Dimensions (in.)		
				A	B	C
STRAIGHT LIQUIDTIGHT FITTINGS						
CI6603	Zinc	3/8	1/2	1.58	0.53	1.18
CI6608		1	1	2.06	0.58	1.81
CI6610		1-1/4	1-1/4		0.61	2.18
CI6612		1-1/2	1-1/2	2.09	0.63	2.51
CI6616		2	2	2.15		3.03
CI6620		2-1/2	2-1/2	3.54	1.02	3.68
CI6624		3	3	4.05	1.07	4.38
CI6632		4	4	4.99	1.15	5.54
STRAIGHT INSULATED LIQUIDTIGHT FITTINGS						
CI6604-IT	Zinc	1/2	1/2	1.62	0.63	1.29
CI6606-IT		3/4	3/4	1.79		1.57
CI6608-IT		1	1	2.16	0.68	1.81
CI6610-IT		1-1/4	1-1/4		0.71	2.18
CI6632-IT		4	4	5.09	1.25	5.54

Tapered threaded hub complete with zinc die cast locknut.