




CI6703 (-IT) / CI6716 (-IT)

IT: with insulated throat.

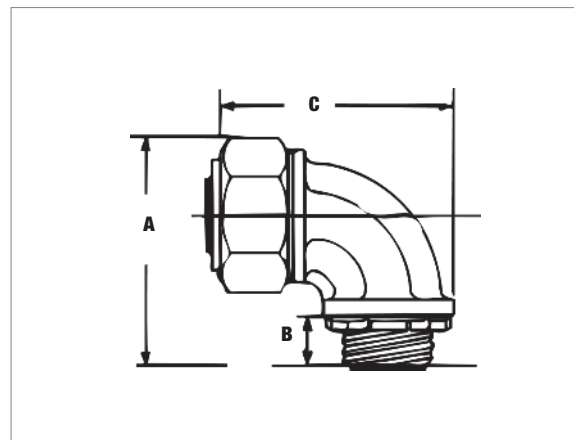

Cat. No.	Alloy	Trade Size (in.)	Knockout Size (in.)	Dimensions (in.)		
				A	B	C
90 DEGREE FITTINGS						
CI6703	Zinc	3/8	1/2	2.11	0.53	2.53
CI6708		1	1	3.46	0.58	3.86
CI6710		1-1/4	1-1/4	3.37	0.67	3.99
CI6712		1-1/2	1-1/2	4.28	0.61	5.04
CI6716		2	2	4.21	0.71	5.06
LT297		2-1/2	2-1/2	4.32	0.88	3.65
LT298		3	3	4.81	0.88	4.32
90 DEGREE FITTINGS – INSULATED THROAT						
CI6703-IT	Zinc	3/8	1/2	2.27	0.63	2.53
CI6704-IT		1/2		2.24		2.46
CI6706-IT		3/4	3/4	2.54	0.65	2.79
CI6708-IT		1	1	3.25	0.68	3.86
CI6710-IT		1-1/4	1-1/4	3.50	0.77	3.99
CI6712-IT		1-1/2	1-1/2	4.30	0.71	5.04
CI6716-IT		2	2	5.16	0.81	5.06

Tapered threaded hub complete with zinc die cast locknut.