




CICG100B560 / CICG150D1375



- Made of corrosion resistant, zinc plated machined steel
- Raintight and strain relieving

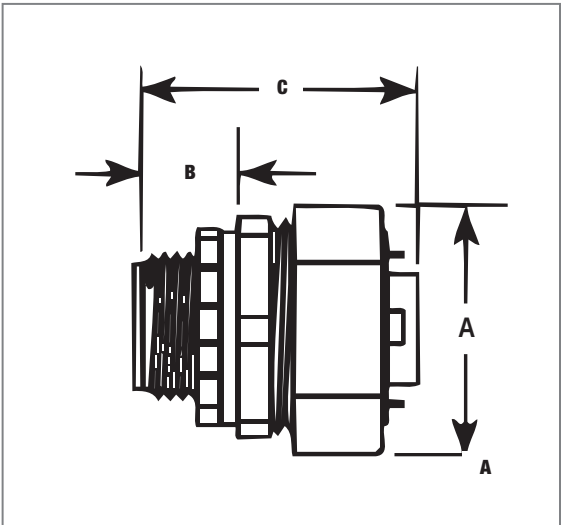

Cat. No.	Trade Size (in.)	Knockout Size (in.)	Cable Dimensions (in.)		Throat Diameter (in.)	Dimensions (in.)					
			Min.	Max		A	B	C			
CORD GRIP FITTINGS (MACHINED STEEL / ZINC PLATED)											
CICG100B560	1	1	0.450	0.560	0.937	1-1/4	1-1/8	1-3/4			
CICG100B750			0.650	0.750							
CICG100B850			0.750	0.850							
CICG100C950			0.850	0.950	1.050				1-1/2	1-3/16	1-7/8
CICG100C1050			0.950	1.050							
CICG125D1050	1-1/4	1-1/4	0.950	1.050	1.375	2					
CICG125D1150			1.050	1.150							
CICG125D1250			1.150	1.250							
CICG125D1375			1.250	1.375							
CICG150D1150	1-1/2	1-1/2	1.050	1.150			1-5/16	2			
CICG150D1250			1.150	1.250							
CICG150D1375			1.250	1.375							