



CI8903 / CI8904




CI8910 / CI8912



CI8905



CI8920 (2-1/2 in.) / CI8922 (3 in.)

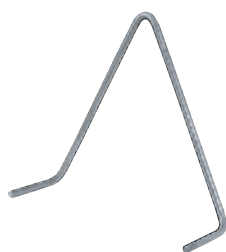

CI8930



CI8932



CIDUCT-1 / CIDUCT-5



CI8960

Cat. No.	Type	Alloy	Trade Size	Working Load
CHAINS				
CI8903	Lion	Zinc Plated Steel	#2	150 lb. / 68 kg
CI8904			#3	125 lb. / 57 kg
CI8910	Jack		#10-T	43 lb. / 19 kg
CI8912			#12	29 lb. / 13 kg
S HOOK				
CI8905		Zinc Plated Steel	#105	75 lb. / 34 kg
SCREW HOOKS				
CI8920		Zinc Plated Steel	#M-10	90 lb. / 40 kg
CI8922			#M-12	115 lb. / 52 kg
FIXTURE HOOKS				
CI8930	90 Degree	Zinc Plated Steel		115 lb. / 52 kg
CI8932	Looped			115 lb. / 52 kg
TIE WIRE (STEEL - GAUGE NO. 16)				
CI8960 (300' Coil)	16 Gauge	Steel / Wire	0.06	125 lb. / 56 kg
DUCT SEAL COMPOUNDS (ASBESTOS FREE)				
CIDUCT-1	1 lb.			
CIDUCT-5	5 lb.			

SEALS IRREGULAR OPENING FROM AIR, DUST OR WATER. Non-hardening sealant that adheres to metal, masonry, wood or plastic. Meets requirement of clause 12.018 CDN ELECTRICAL CODE Part 1. Safe and easy to use. - NON-CORROSIVE - NON-TOXIC - NO ASBESTOS - NO UNPLEASANT ODOR - WILL NOT STAIN OR HARM HANDS. TEMPERATURE Continuous operating range: -34 °C to 88 °C (-30 °F to 190 °F) Minimum. Temperature for installation: -12 °C (10 °F).