



Material

Most products are manufactured from hot rolled carbon steel bars or hot rolled strip steel. Pipe rollers are cast iron.

Design Loads

Where design loads are indicated, they provide for a safety factor of 3 in conformance with the American Standard Code for Pressure Piping.


Finishes and Special Materials

The standard finish is Electrogalvanized (EGC) or GoldGalv®. Some products are offered in Aluminum and Stainless Steel where noted.

Quik Clamp II



Design Load 1 has a safety factor of 4.
Design Loads 2 and 3 have a safety factor of 1.

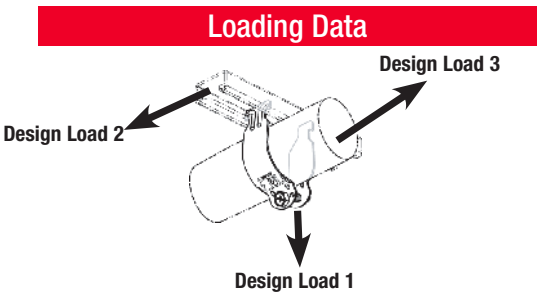

Cat. No.	Trade Size in. (mm)		Qty. per Box	Wt./C lb.	Design Load 1	Design Load 2	Design Load 3
	EMT	Rigid Conduit			Static Load Limit lb. (kg)	Static Load Limit lb. (kg)	Static Load Limit lb. (kg)
TBQC050	1-5/16 (33.5)	1-1/4 (31.5)	100	10	200 (90)	50 (23)	50 (23)
TBQC075	1-3/4 (44.5)	1-11/16 (43)		12			
TBQC100	1-13/16 (46)	1-3/4 (44.5)		13			
TBQC125	2-1/8 (54)	2 (51)	50	15			
TBQC150	2-3/8 (60.5)	2-3/16 (55.5)		16			
TBQC200	2-5/8 (66.5)	2-1/2 (63.5)		19			
TBQC250	3-1/16 (78)	3-1/16 (78)	25	29	350 (158)	50 (23)	50 (23)
TBQC300	3-11/16 (93.5)	3-11/16 (93.5)		34			
TBQC350	4-3/16 (106.5)	4-3/16 (106.5)		38			
TBQC400	4-11/16 (119)	4-11/16 (119)		42			