
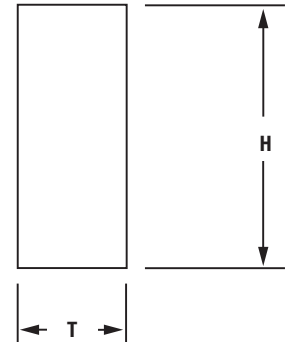


Ground Rod Connectors Figure 6

Blackburn®

- Material: High-conductivity copper.
- Acceptable for direct burial.

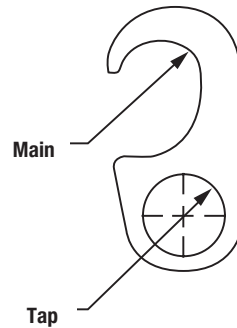

Cat. No.	Application		Cable to rebar application		Dimensions in. (mm)		Dies for TBM14M, 13100A or TBM15I
	Main	Tap	Main	Tap	T	H	
54855	1/0 Str.–250 kcmil or 1/2"–5/8" Rod	#4 Sol.–#2 Str.	#3 Rebar 3/8 thru 1/2" #4 Rebar	#4 Sol.–#2 Str.	0.75 (19.1)	1.94 (49.3)	15G86A [1]
54860	1/0 Str.–250 kcmil or 1/2"–5/8" Rod	1/0 Str.–2/0 Str.		1/0 Str.–2/0 Str.		2.19 (55.6)	15G86R [1]
54865CK	1/0 Str.–250 kcmil or 1/2"–5/8" Rod	3/0 Str.–250 kcmil		3/0 Str.–250 kcmil		15G86R [1]	
54875	#6 Sol.–#2 Str.	#6 Sol.–#2 Str.	–	–		2.56 (65.0)	15501A [1]
54885	250 kcmil–500 kcmil or 5/8"–3/4" Rod	#4 Sol.–#2 Str.	–	–		1.94 (49.3)	15G126R [1]
54890	250 kcmil–500 kcmil or 5/8"–3/4" Rod	1/0 Str.–2/0 Str.	#5 Rebar 5/8 thru 3/4" #6 Rebar	1/0 Str.–2/0 Str.		2.13 (54.1)	15G126R [1]
54895	250 kcmil–500 kcmil or 5/8"–3/4" Rod	3/0 Str.–250 kcmil		3/0 Str.–250 kcmil		2.19 (55.6)	15G126R [1]
54900	250 kcmil–500 kcmil or 5/8"–3/4" Rod	350 kcmil–500 kcmil		350 kcmil–500 kcmil	1.13 (28.7)	2.44 (62.0)	15G121R [3]

* Number of crimps.