
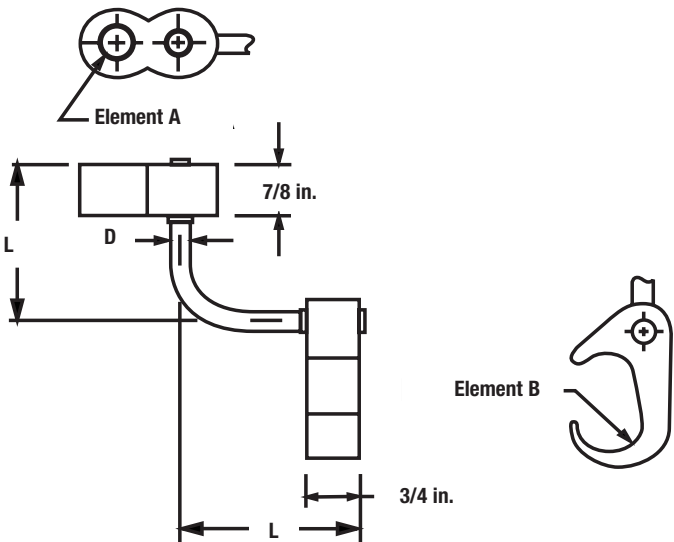


Ground Rod Connectors

Figure 6 to Figure 8

Blackburn®

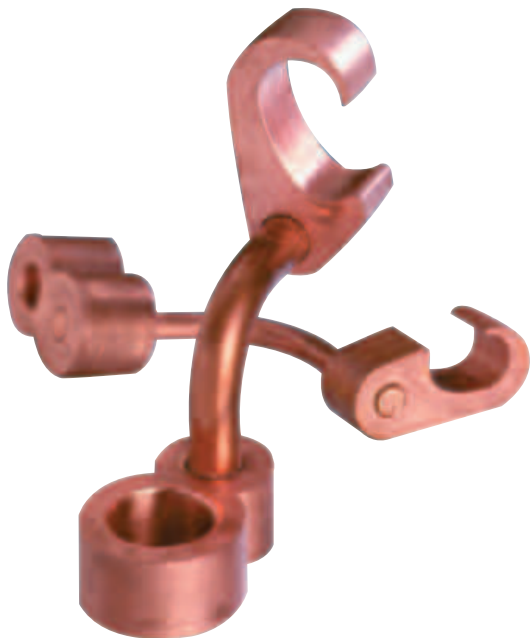

Cat. No.	A Ground Rod in. (mm)	B Cable Range	Dimensions in. (mm)		Dies for TBM14M, 13100A or TBM15I	
			D	L	Element A	Element B
54855LR12*	1/2 (12.7)	2 AWG–250 kcmil	0.31 (7.8)	2.50 (63.5)	15G121R [2]	15G86R [1]
54885LR12*		250 kcmil–500 kcmil				15G126R [1]
54865LR58*	5/8 (16.0)	2 AWG–250 kcmil				15G86R [1]
54895LR58*		250 kcmil–500 kcmil				15G126R [1]
54875LR34*	3/4 (19.1)	2 AWG–250 kcmil	0.50 (12.7)	2.63 (66.8)		15G86R [1]
54900LR34*		250 kcmil–500 kcmil				15G126R [1]
54910LR100	1 (25.4)	2 AWG–250 kcmil				15G86R [1]
54920LR100		250 kcmil–500 kcmil				15G126R [1]

*Tin-plated version available for galvanized ground rods. Add suffix -TP to Cat. No.
Use 15500TB adaptor for TBM15-Ton tool.

***** Number of crimps.

