


Dimensions

Dimensions are approximate and subject to change

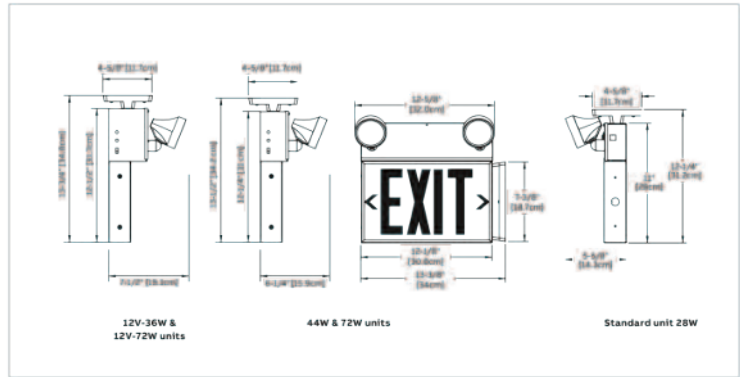

Metal Combination Unit

- Dual input voltages 120/347VAC
- Comes pre-assembled for quick, easy installation
- Universal mounting – end, wall or ceiling
- Easy access to wiring entry for all mounting options
- Canopy mounting system designed specifically for ease of installation
- Universal, field-selectable chevrons (knockout)
- Energy efficient – complete unit consumes less than 5 watts
- Meets or exceeds CSA 22.2 No. 141 requirements
- Long life, energy-efficient LED light source, mounted inside the exit housing, not on the faceplate
- Warranty details at: www.emergi-lite.ca/



Series	Colour	Voltage	Powerpack	Charger type	Options	# of heads	Head style / Wattage
METAL COMBINATION UNIT							
EX10 = 6V Unit	B= black G = grey* W= factory white *Black heads	Blank = 120/347VAC -2 = 120/277VAC	-P= 6V-28W -P4= 6V-44W -P7= 6V-72W	Blank= standard	Blank= no options D= time delay (15 minutes) G= green legem TP= tamper-proof screws**	/0= no heads /1= one head /2= two heads	LA= MR16 LED, 6V-4W LB= MR16 LED, 6V-5W

** 990.0119-E= tamper-proof bit (sold separately)