


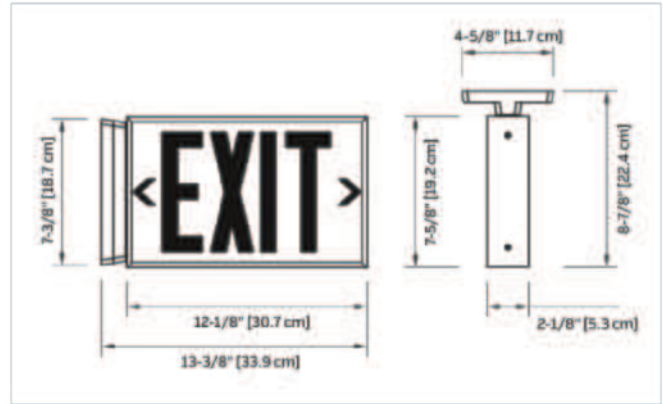

Dimensions

Dimensions are approximate and subject to change



All Metal Exit Sign

- Two-wires universal AC input
- Pre-assembled for quick, easy installation
- Universal mounting – end, wall or ceiling
- Supplied with two stencil plates, red diffusing lenses and backplate
- Easy access to wiring entry for all mounting options
- Canopy mounting system designed specifically for ease of installation
- Universal, field-selectable chevrons (knockout)
- Energy efficient – consumes less than 3 watts in AC or DC mode
- Normal AC and emergency DC operation – 120 to 347 volt AC input; 6 to 24 volt DC input
- Warranty details at: www.emergi-lite.ca/



Series	Colour	Power Source and Voltage	Options
ALL METAL EXIT SIGN			
EX10 = LED EXIT sign / Universal mount	B= black TA= textured aluminum W= factory white	-U= universal voltage, 120 to 347VAC, 6 to 24VDC -U00= 120 to 347VAC, no DC -U36= 120/277/347VAC, 36VDC -U48= 120/277/347VAC, 48VDC -U120= 120/347VAC, 120VDC -EM120-2W= 120VAC, 120VDC, 2 wires -I= self-powered, 120 to 347VAC -IDN2= self-powered diagnostic, Ni-Cd 120/277VAC, (90 minutes) -IDN3= self-powered diagnostic, Ni-Cd 120/347VAC, (90 minutes)	-G= green legend -TP= tamper-proof screws* -VRTP1= vandal resistant shield with tamper-proof screws, single face** -VRTP2= vandal resistant shield with tamper-proof screws, double face** * 990.0119-E= tamper-proof bit (sold separately)

** Supply as single face