




**Dimensions**

Dimensions are approximate and subject to change

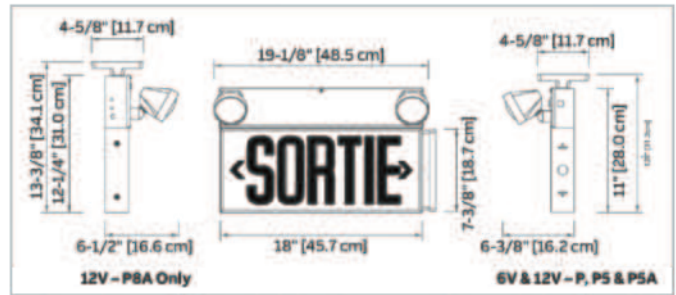

**All Metal “Sortie” Combination Unit**

- Pre-assembled for ease of installation
- Metal housing with baked enamel finish - will not yellow
- Easy access to wiring entry
- Exit sign with long life, ALINGAP LED light source
- Energy efficient – consumes less than 3 watts in stand-by mode

- Power pack comes with premium lead-calcium battery
- Meets or exceeds CSA 22.2 No. 141 requirements
- Warranty details at: [www.emergi-lite.ca/](http://www.emergi-lite.ca/)



Series	Colour	Voltage	Voltage/Supply	Options	# of heads	Head style/wattage
<b>ALL METAL “SORTIE” COMBINATION UNIT</b>						
SR12= Single face, wall or ceiling mount	B= black TA= textured aluminum W= factory white	Blank = 120/347VAC	-P= 6V-27W -P5= 6V-50W -P5A= 12V-50W -P8A= 12V-80W	-Blank= no options -D3= time delay (15 minutes) -TP= tamper-proof screws*	/0= no heads /1= one head /2= two heads	LA= MR16 LED, 6V-4W LB= MR16 LED, 6V-5W LG= MR16 LED, 12V-4W LI= MR16 LED, 12V-5W LJ= MR16 LED, 12V-6W

\* 990.0119-E= tamper-proof bit (sold separately)