


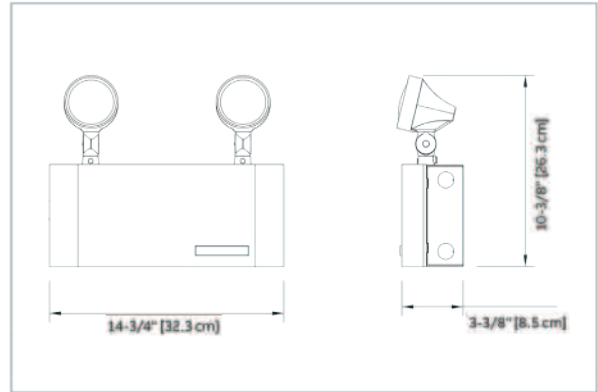

Dimensions

Dimensions are approximate and subject to change



Steel, compact, 6V

- Compact steel cabinet with corrosion-resistant undercoating
- Quick and easy installation – pre-assembled cordset, no batteries or board to remove before installation
- Universal Spider knockout pattern for junction box mounting
- Fully automatic solid-state charger with test switch and AC-on pilot light
- Sealed dust-proof transfer relay circuit and low-voltage disconnect
- Long-life, maintenance-free sealed lead battery
- Warranty details at: www.emergi-lite.ca/

Series	Capacity	Colour	Voltage	Options	# of Heads	Heads Style / Wattage
STEEL, COMPACT, 6V						
06JMLC = 6V	27= 27W 44= 44W 72= 72W	BK= black Blank= factory white	Blank= 120VAC c/w linecord -2= 277VAC input -3= 120/347VAC input	Blank= no options CT= cab-tire U= auto-diagnostics* UN= auto-diagnostics, non-audible* LW= twist-lock plug**	/0= no heads /1= one head /2= two heads	LA= MR16 LED, 6V-4W LB= MR16 LED, 6V-5W LG= MR16 LED, 12V-4W LI= MR16 LED, 12V-5W LJ= MR16 LED, 12V-6W

* Not available in 6V-72W
** 120V is standard